


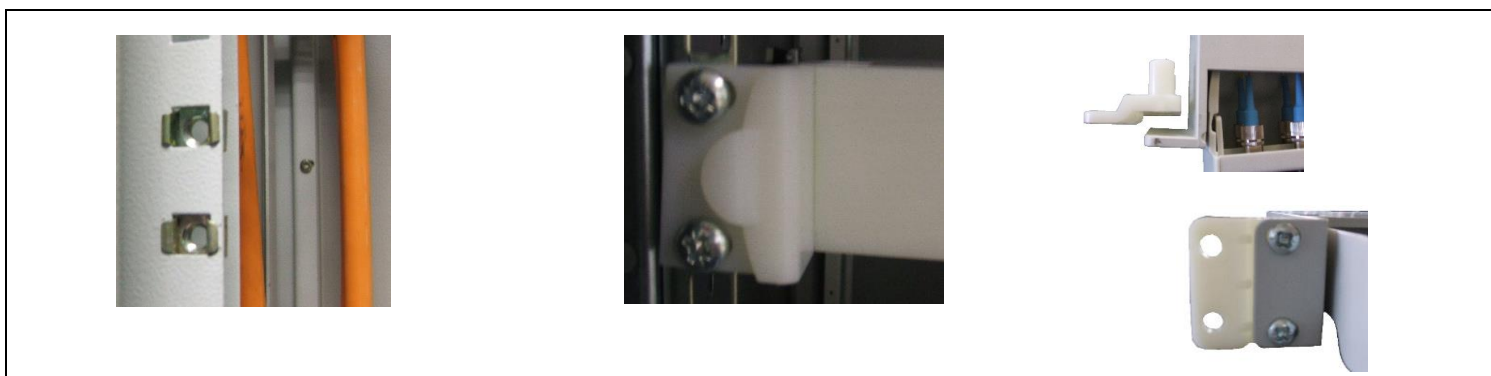
INSTALLATION INSTRUCTION

**OAsys® INTERNAL PLANT
PLASTIC SPLITTER SHELF**


Component Parts (pictures not to scale)

<p>1 Splitter Shelf Assembly Qty 1</p> 	<p>2 Fixing Kit Contents as listed below: -</p> <ol style="list-style-type: none"> 1. 2x ETSI Mounting bracket 2. 4x Cage Nut 3. 4x M6x12 Sems Screw 4. 4x No.6x 5/8 Plastite screw
--------------------------------------------------------------------------------------------------------------------------------	--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Mounting the shelf to the Rack



- Fit four cage nuts (two each side) as shown then screw the shelf into place using the M6 SEMS screws
- If ETSI brackets are required use the plastite screws to fit the ETSI bracket to the shelf and then mount into the rack as described above.

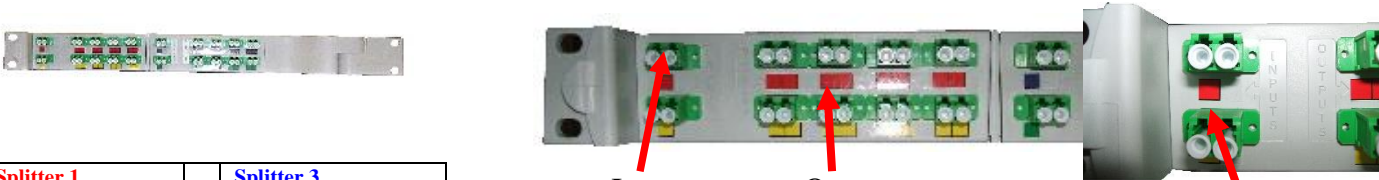

Splitter 1	Splitter 3
Splitter 2	Splitter 4

- Identify the splitter you require. The splitters are identified as shown above.
- Plug your input into the input port on the front of the panel. The live input port is on the left.
- Plug your output patchcord into one of the output ports that is connected to the input port you have selected.



Clean before you connect.

It is important that all fibre connectors and adapters are cleaned prior to mating using approved local practice. Failure to clean may result in either poor signal performance and/or permanent damage to the connector end faces.